

## Pull Tape

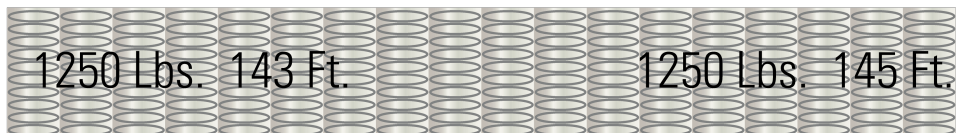
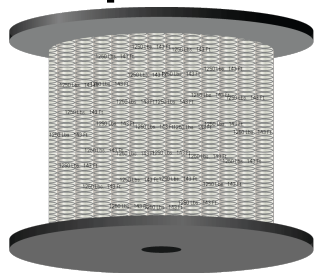


Image not to scale. See Table 1 for dimensions.

### CONSTRUCTION:

- High strength measuring and flat woven pulling tape
- 100% polyester for low absorption of moisture
- Resistant to conduit cutting/burning-through during pulling
- Low elongation for safety and accuracy
- Printed with sequential footage markings for easy locating

### Weights, Measurements, and Packaging

| TENSILE STRENGTH | APPROX. WIDTH | SPOOL LENGTH | SPOOL SIZE | WEIGHT PER SPOOL |
|------------------|---------------|--------------|------------|------------------|
| lbs              | inch          | feet         | inch       | lbs              |
| 1130             | 0.4375        | 3000         | 14 x 12    | 22               |
| 1130             | 0.4375        | 5000         | 14 x 12    | 37               |
| 1250             | 0.5           | 3000         | 1 x 12     | 25               |
| 1250             | 0.5           | 5000         | 14 x 12    | 40               |
| 1800             | 0.625         | 3000         | 14 x 12    | 30               |
| 1800             | 0.625         | 5000         | 18 x 13    | 45               |
| 2500             | 0.625         | 3000         | 18 x 13    | 46               |
| 2500             | 0.625         | 5000         | 18 x 13    | 66               |

### Options

- Available in 1130#, 1250#, 1800#, and 2500# tensile strength
- 1800# and 2500# tape also available with a locatable tracer wire pre-installed
- Available on a reel
- Available pre-installed in conduit

