

## Burglar Alarm Cable

Burglar Alarm cable Solid and Stranded CM/CL2 Rated

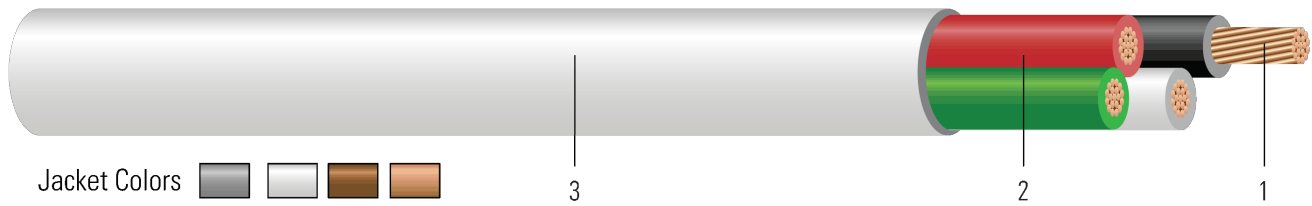


Image not to scale. See Table 1 for dimensions.

### CONSTRUCTION:

1. **Conductor:** 22 AWG solid or stranded
2. **Insulation:** Foam Polypropylene
3. **Overall Jacket:** Polyvinyl Chloride (PVC) White, Gray, Brown, Beige

### APPLICATIONS AND FEATURES:

Burglar alarm interconnect cables to controls systems, Class 2 Power Limited Circuit Cable and Communications Cable for General Purpose Applications

### SPECIFICATIONS:

- UL 13 Power-Limited Circuit Cables
- UL 444 CM/CL2
- UL 1685 Vertical-Tray Fire Propagation and Smoke Release Test

### SAMPLE PRINT LEGEND:

SOUTHWIRE® SIGNAL® 22 AWG C{ETL}US CM/CL2 75°C SUN RES - CMX OUTDOOR - CMH FT1 -- {MM/DD/YY}  
{HH:MM} {SEQUENTIAL FOOTAGE MARKS} SEQ FEET



**Table 1 – Physical and Electrical Data**

| Stock Number | Cond. Size | Cond. Number | Cond. Strands | Diameter Over Cond. | Insulation Color | Insul. Thickness | Approx. OD | Copper Weight | Approx. Weight |
|--------------|------------|--------------|---------------|---------------------|------------------|------------------|------------|---------------|----------------|
|              | AWG        | No.          | strands       | inch                |                  | mil              | inch       | lb /1000ft    | lb /1000ft     |
| 22 AWG       |            |              |               |                     |                  |                  |            |               |                |
| 96238        | 22         | 4            | Solid         | 0.025               | BK, RD, YW, GN   | 6                | 0.117      | 7             | 12             |

All dimensions are nominal and subject to normal manufacturing tolerances

◊ Cable marked with this symbol is a standard stock item

