



# Burglar Alarm Cable

Burglar Alarm cable Solid and Stranded CM/CL2 Rated

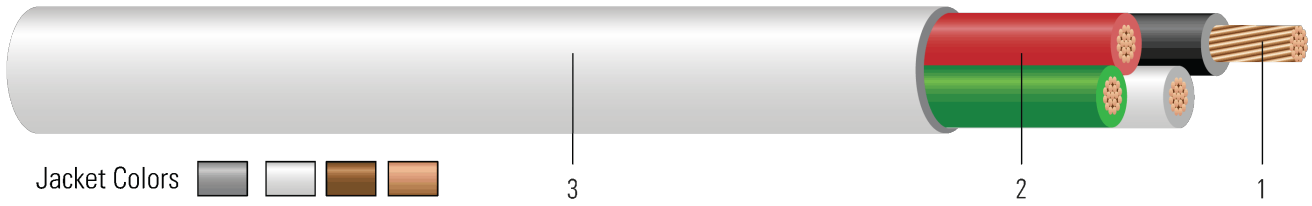


Image not to scale. See Table 1 for dimensions.

## CONSTRUCTION:

1. **Conductor:** 22 AWG solid or stranded
2. **Insulation:** Foam Polypropylene
3. **Overall Jacket:** Polyvinyl Chloride (PVC) White, Gray, Brown, Beige

## APPLICATIONS AND FEATURES:

Burglar alarm interconnect cables to controls systems, Class 2 Power Limited Circuit Cable and Communications Cable for General Purpose Applications

## SPECIFICATIONS:

- UL 13 Power-Limited Circuit Cables
- UL 444 CM/CL2
- UL 1685 Vertical-Tray Fire Propagation and Smoke Release Test

## SAMPLE PRINT LEGEND:

SOUTHWIRE® SIGNAL® 22 AWG C{ETL}US CM/CL2 75°C SUN RES - CMX OUTDOOR - CMH FT1 -- {MM/DD/YY}  
{HH:MM} {SEQUENTIAL FOOTAGE MARKS} SEQ FEET





**Table 1 – Physical and Electrical Data**

Stock Number	Cond. Size AWG	Cond. Number No.	Cond. Strands strands	Diameter Over Cond. inch	Color	Insul. Thickness mil	Approx. OD inch	Copper Weight lb /1000ft	Approx. Weight lb /1000ft
22 AWG									
96222	22	2	Solid	0.025	RD,GN	6	0.102	3	7

All dimensions are nominal and subject to normal manufacturing tolerances

◊ Cable marked with this symbol is a standard stock item

TBA stock codes are estimations only and actual product may vary. Please wait until a stock code is assigned to purchase connectors and/or fittings.

**Insulation Colors**

Stock Number	Size	Conductor Number	Black	Red	Yellow	White	Green
96222	22	2	Black	Grey	Grey	Grey	Green
96238	22	4	Black	Red	Yellow	White	Green
51101	22	2	Black	Red	Grey	Grey	Grey
51112	22	4	Black	Red	White	White	Green

