



## Burglar Alarm Cable

Burglar Alarm cable Solid and Stranded CM/CL2 Rated

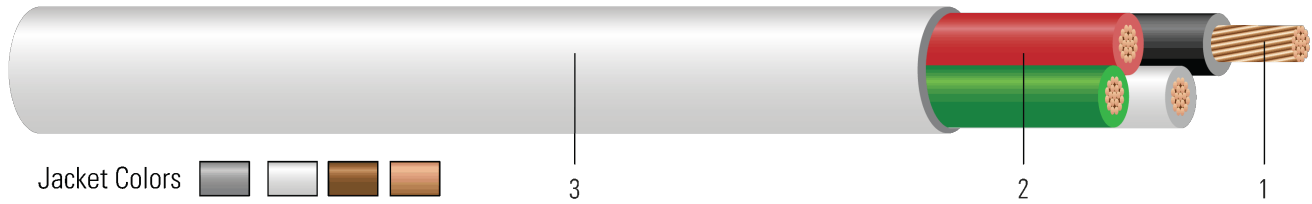


Image not to scale. See Table 1 for dimensions.

### CONSTRUCTION:

1. **Conductor:** 22 AWG solid or stranded
2. **Insulation:** Foam Polypropylene
3. **Overall Jacket:** Polyvinyl Chloride (PVC) White, Gray, Brown, Beige

### APPLICATIONS AND FEATURES:

Burglar alarm interconnect cables to controls systems, Class 2 Power Limited Circuit Cable and Communications Cable for General Purpose Applications

### SPECIFICATIONS:

- UL 13 Power-Limited Circuit Cables
- UL 444 CM/CL2
- UL 1685 Vertical-Tray Fire Propagation and Smoke Release Test

### SAMPLE PRINT LEGEND:

SOUTHWIRE® SIGNAL® 22 AWG C{ETL}US CM/CL2 75°C SUN RES - CMX OUTDOOR - CMH FT1 -- {MM/DD/YY}  
{HH:MM} {SEQUENTIAL FOOTAGE MARKS} SEQ FEET





**Table 1 – Physical and Electrical Data**

Stock Number	Cond. Size	Cond. Number	Cond. Strands	Diameter Over Cond.	Insulation Color	Insul. Thickness	Approx. OD	Copper Weight	Approx. Weight
	AWG	No.	strands	inch		mil	inch	lb /1000ft	lb /1000ft
22 AWG									
51112	22	4	7	0.029	BK, RD, WE, GN	6	0.126	9	14

All dimensions are nominal and subject to normal manufacturing tolerances  
 ◇ Cable marked with this symbol is a standard stock item

